

Technical specifications:

- 32-bit ARM CPU
- Hardware interfaces (UART, SPI, ADC, I²C, clocks, timers etc.)
- Supply voltage: 1,85 - 3,8 VDC
- Operating temperature: -40 to +85 °C
- Dimensions (W x L x H): 6,5 mm x 6,5 mm x 1,4 mm

Example photographs of representative samples:

Figure 1 BGM121 top

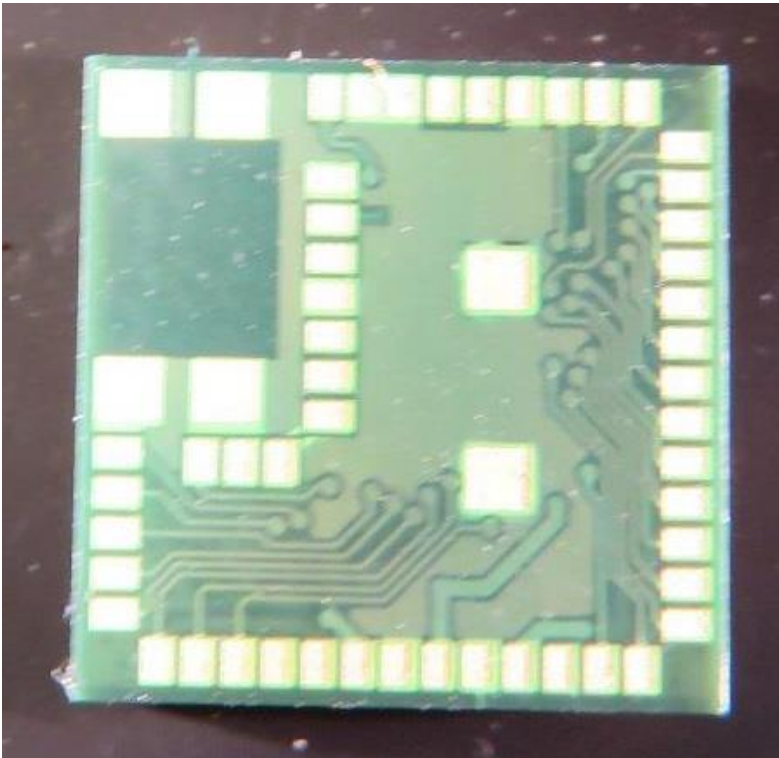


Figure 2 BGM121 bottom

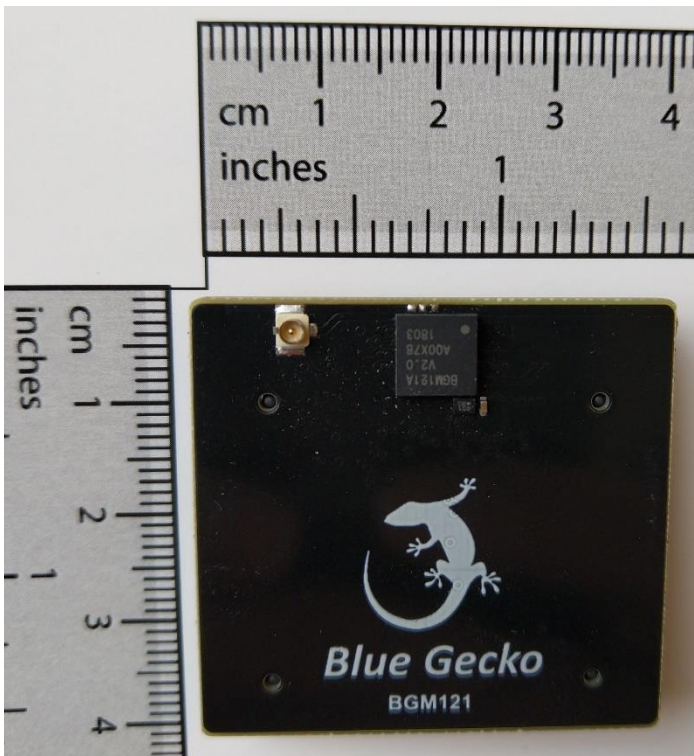


Figure 3 BGM121 on evaluation board

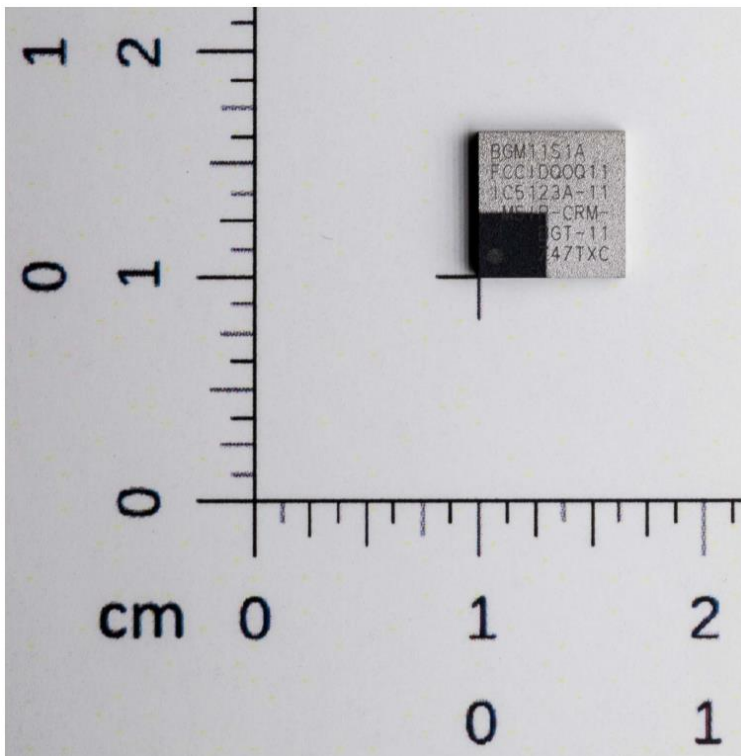


Figure 4 BGM11S top

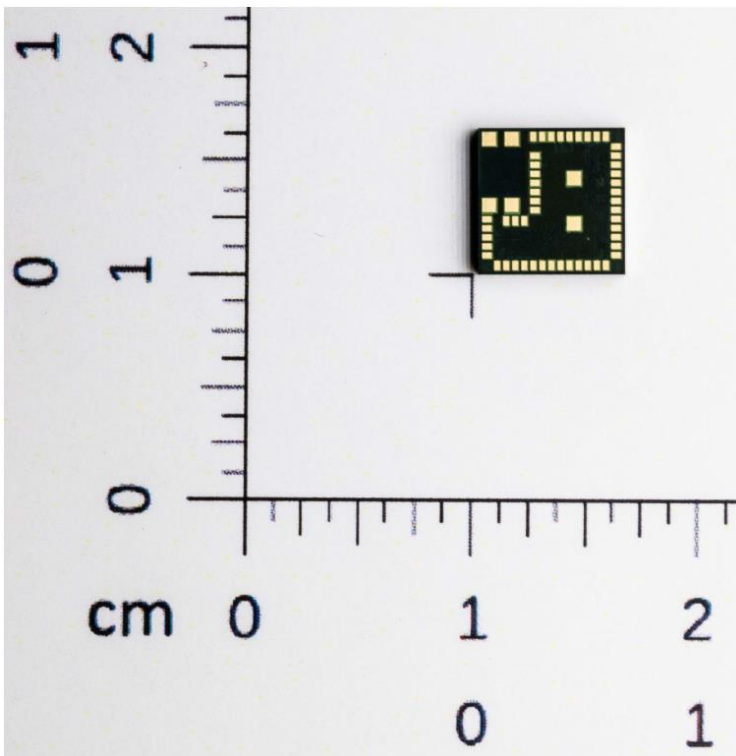


Figure 5 BGM11S bottom